


CPI Solutions Guide

CABLE MANAGEMENT PRODUCTS


Evolution® Cable Management	
<i>For Rack Systems. For high-density applications; features moveable mid-sections, cable guides and doors with two-point latches. Also available in Glacier White (-EXX).</i>	
35511-703	g1 Single-Sided Vertical, 7'H x 6"W x 13.2"D (2.1 m x 150 mm x 335 mm), Black
35512-703	g1 Single-Sided Vertical, 7'H x 8"W x 13.2"D (2.1 m x 200 mm x 335 mm), Black
35514-703	g1 Single-Sided Vertical, 7'H x 12"W x 13.2"D (2.1 m x 300 mm x 335 mm), Black
35521-703	g2 Double-Sided Vertical, 7'H x 6"W x 24.5"D (2.1 m x 150 mm x 622 mm), Black
35522-703	g2 Double-Sided Vertical, 7'H x 8"W x 24.5"D (2.1 m x 200 mm x 622 mm), Black
35524-703	g2 Double-Sided Vertical, 7'H x 12"W x 24.5"D (2.1 m x 300 mm x 622 mm), Black
35571-703	g3 Combination Vertical, 7'H x 6"W x 20.2"D (2.1 m x 150 mm x 513 mm), Black
35572-703	g3 Combination Vertical, 7'H x 8"W x 20.2"D (2.1 m x 200 mm x 513 mm), Black
35574-703	g3 Combination Vertical, 7'H x 12"W x 20.2"D (2.1 m x 300 mm x 513 mm), Black
35441-701	Horizontal, Single-Sided, 1U x 19"EIA x 8.2"D (208 mm), Black
35541-702	Horizontal, Single-Sided, 2U x 19"EIA x 8.2"D (208 mm), Black
35541-703	Horizontal, Single-Sided, 3U x 19"EIA x 8.2"D (208 mm), Black
<i>Other heights and widths available.</i>	
Velocity® Cable Management	
<i>For Rack Systems. Cost-effective solution; features snap-together design, cable guides and snap on covers.</i>	
13902-703	Single-Sided Vertical, 80.5"H x 6"W x 9.8"D (2045 mm x 152 mm x 249 mm), Black
13904-703	Single-Sided Vertical, 80.5"H x 10"W x 10.3"D (2045 mm x 254 mm x 262 mm), Black
13905-703	Single-Sided Vertical, 80.5"H x 12"W x 10.4"D (2045 mm x 305 mm x 264 mm), Black
13912-703	Double-Sided Vertical, 80.5"H x 6"W x 16.6"D (2045 mm x 152 mm x 422 mm), Black
13914-703	Double-Sided Vertical, 80.5"H x 10"W x 17.5"D (2045 mm x 254 mm x 445 mm), Black
13915-703	Double-Sided Vertical, 80.5"H x 12"W x 17.8"D (2045 mm x 305 mm x 446 mm), Black
13930-701	Horizontal, Single-Sided, 1U x 19"EIA x 5.9"D (150 mm), Black
13930-702	Horizontal, Single-Sided, 2U x 19"EIA x 5.9"D (150 mm), Black
13930-703	Horizontal, Single-Sided, 3U x 19"EIA x 5.9"D (150 mm), Black
<i>Other heights and widths available.</i>	
Master Cabling Section (MCS)	
<i>For Rack Systems. Features cable guides and hinged latching covers.</i>	
30092-703	Single-Sided, 7'H x 6"W x 8.08"D (2.1 m x 150 mm x 205.2 mm)
30093-703	Single-Sided, 7'H x 10"W x 8.08"D (2.1 m x 250 mm x 205.2 mm)
30095-703	Double-Sided, 7'H x 6"W x 16.15"D (2.1 m x 150 mm x 410.2 mm)
30096-703	Double-Sided, 7'H x 10"W x 16.15"D (2.1 m x 250 mm x 410.2 mm)
40092-703	Single-Sided, Extended Fingers, 7'H x 6"W x 10.62"D (2.1 m x 150 mm x 269.7 mm)
40093-703	Single-Sided, Extended Fingers, 7'H x 10"W x 10.62"D (2.1 m x 250 mm x 269.7 mm)
40095-703	Double-Sided, Extended Fingers, 7'H x 6"W x 21.23"D (2.1 m x 150 mm x 539.2 mm)
40096-703	Double-Sided, Extended Fingers, 7'H x 10"W x 21.23"D (2.1 m x 250 mm x 539.2 mm)
<i>Color listed is black. Other heights and finishes available.</i>	
Combination Cabling Section (CCS)	
<i>For Rack Systems. Double-Sided combination cable manager with cable guides and hinged latching covers.</i>	
30161-703	7'H x 3.65"W x 12.24"D (2.1 m x 92.7 mm x 311 mm), Black
30162-703	7'H x 6"W x 12.24"D (2.1 m x 150 mm x 311 mm), Black
30163-703	7'H x 10"W x 12.24"D (2.1 m x 250 mm x 311 mm), Black
40098-703	Extended Fingers, 7'H x 6"W x 14.94"D (2.1 m x 150 mm x 379.5 mm), Black
40099-703	Extended Fingers, 7'H x 10"W x 14.94"D (2.1 m x 250 mm x 379.5 mm), Black
40100-703	Extended Fingers, 7'H x 12"W x 14.94"D (2.1 m x 300 mm x 379.5 mm), Black
<i>Other heights available. Also available in Glacier White (-EXX).</i>	
Vertical Cable Management for Cabinets	
<i>Finger Cable Managers for 45U F-Series TeraFrame® Gen 3 Cabinet System. Also available in Glacier White.</i>	
39120-C03	Finger Cable Manager, 4"D (102 mm) for 23.6"W (600 mm) cabinets, Black
39112-C14	Finger Cable Manager, 8.4"D (213 mm) for 27.6"W (700 mm) cabinets, Black
39112-C25	Finger Cable Manager, 8.4"D (213 mm) for 31.5"W (800 mm) cabinets, Black
<i>Cable Lashing Bracket for 45U F-Series TeraFrame® Gen 3 Cabinet System. Also Available in Glacier White.</i>	
39124-C03	Cable Lashing Bracket, 1.6"W (41 mm), for 45U cabinets, Black
<i>Cable Lashing Managers for 45U N-Series TeraFrame® Gen 3 Network Cabinet System. Also available in Glacier White.</i>	
39380-C03	Cable Lashing Manager, Slim, 5.1" (130 mm), for 45U cabinets, Black
39381-C03	Cable Lashing Manager, Wide, 9.8" (250 mm), for 45U cabinets, Black
<i>Ring Cable Manager for 42U GF-Series GlobalFrame® Gen 2 Cabinet System. Also available in Glacier White.</i>	
39087-C00	Ring Cable Manager, 4.5"D (114 mm) for 42U, 23.6"W (600 mm) cabinets, Black
39088-C00	Ring Cable Manager, 5.0"D (127 mm) for 42U, 27.6"W (700 mm) cabinets, Black
39089-C00	Ring Cable Manager, 5.0"D (127 mm) for 42U, 31.5"W (800 mm) cabinets, Black
<i>Cable Ring Manager for 45U M-Series MegaFrame® Cabinets. Color is black.</i>	
12465-707	2.3"W x 5.5"D (58 mm x 140 mm) for 27.3"W (694 mm) cabinets
<i>Other cable management options and finishes are available.</i>	

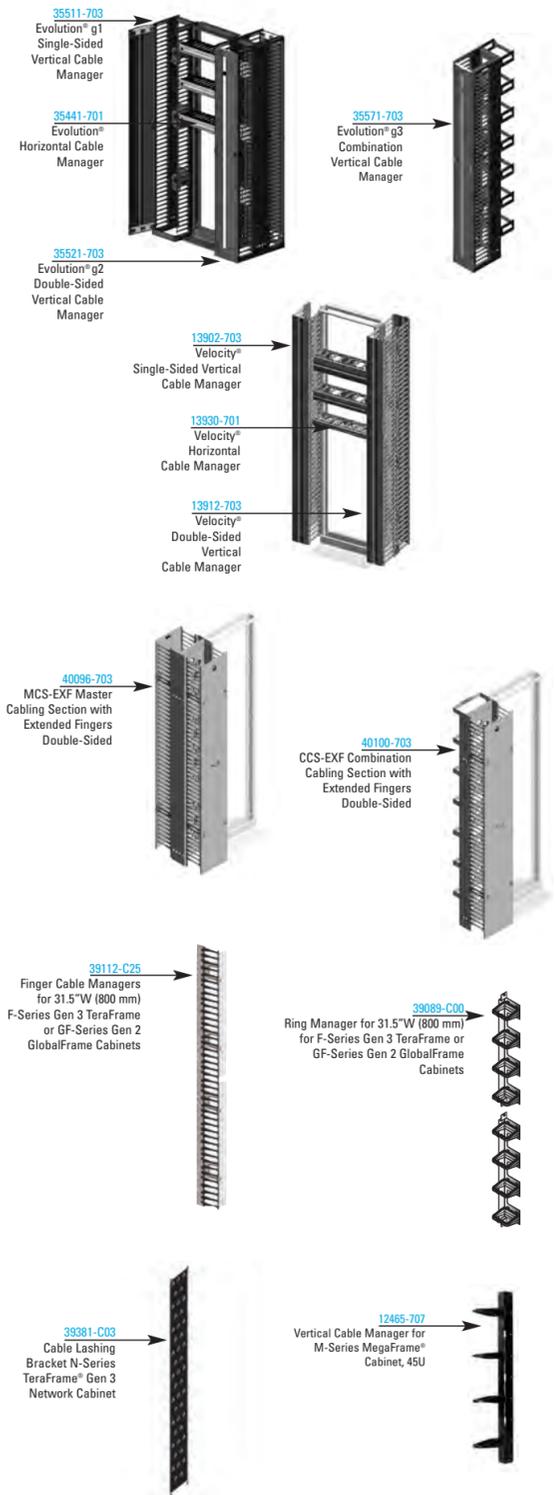


F-SERIES TERAFRAME GEN 3 CABINET SYSTEM WITH VERTICAL EXHAUST DUCT INSTALLED




GF-SERIES GLOBALFRAME GEN 2 CABINET SYSTEM WITH VERTICAL EXHAUST DUCT INSTALLED

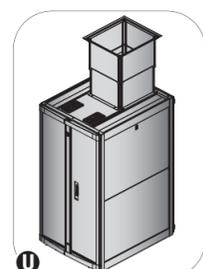

N-SERIES TERAFRAME GEN 3 NETWORK CABINET WITH VERTICAL EXHAUST DUCT INSTALLED

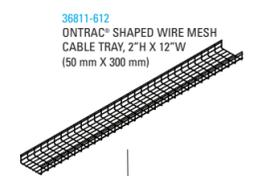

36811-612 ONTRAC® SHAPED WIRE MESH CABLE TRAY, 2"H X 12"W (50 mm X 300 mm)

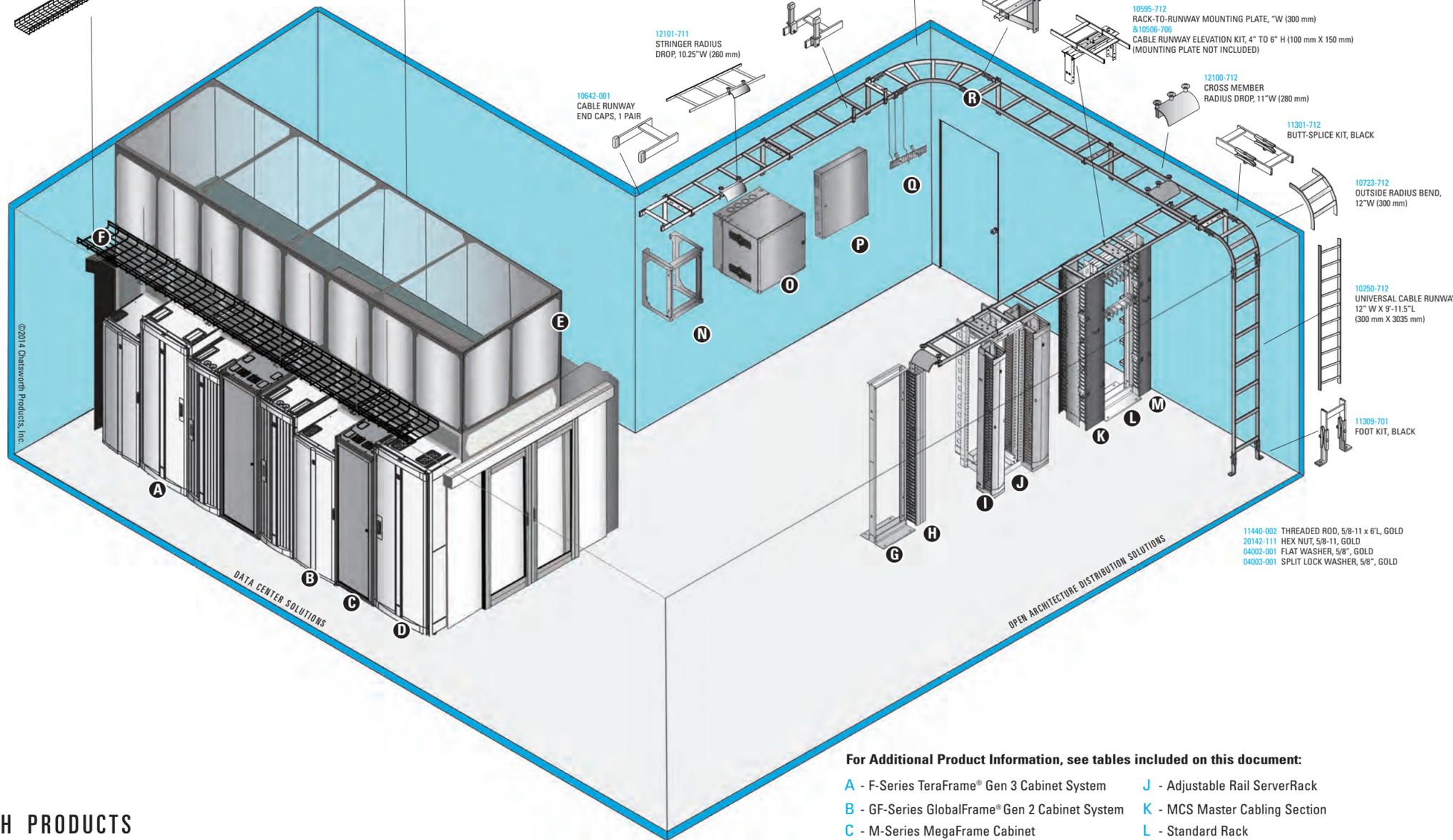

AISLE CONTAINMENT SOLUTIONS BY CPI:
 BUILD TO SPEC (BTS) HOT AISLE CONTAINMENT (HAC) SOLUTION
 CABINET SUPPORTED HOT AISLE CONTAINMENT (HAC) - NOT SHOWN
 FRAME SUPPORTED HOT AISLE CONTAINMENT (HAC) - NOT SHOWN
 CABINET SUPPORTED COLD AISLE CONTAINMENT (CAC) - NOT SHOWN
 AISLE CONTAINMENT DOOR ASSEMBLY

- 10822-712** CABLE RUNWAY E-BEND, 12"W (300 mm)
- 10596-708** CABLE RUNWAY RETAINING POST
- 11746-712** TRIANGULAR SUPPORT BRACKET, STEEL, 12"W (300 mm)
- 10595-712** RACK-TO-RUNWAY MOUNTING PLATE, "W (300 mm) & 10506-706 CABLE RUNWAY ELEVATION KIT, 4" TO 6" H (100 mm X 150 mm) (MOUNTING PLATE NOT INCLUDED)
- 12100-712** CROSS MEMBER RADIUS DROP, 11"W (280 mm)
- 11301-712** BUTT-SPLICE KIT, BLACK
- 10723-712** OUTSIDE RADIUS BEND, 12"W (300 mm)
- 10259-712** UNIVERSAL CABLE RUNWAY, 12" W X 9" X 11.5" L (300 mm X 303 mm)
- 11309-701** FOOT KIT, BLACK
- 11440-002** THREADED ROD, 5/8-11 x 6"L, GOLD
- 20142-111** HEX NUT, 5/8-11, GOLD
- 04002-001** FLAT WASHER, 5/8", GOLD
- 04003-001** SPLIT LOCK WASHER, 5/8", GOLD

- For Additional Product Information, see tables included on this document:**
- A** - F-Series TeraFrame® Gen 3 Cabinet System
 - B** - GF-Series GlobalFrame® Gen 2 Cabinet System
 - C** - M-Series MegaFrame Cabinet
 - D** - N-Series TeraFrame® Gen 3 Network Cabinet
 - E** - Build To Spec (BTS) Hot Aisle Containment
 - F** - OnTrac® Wire Mesh Cable Tray
 - G** - Velocity® Standard Pack
 - H** - Velocity® Vertical Cable Management
 - I** - Evolution® Vertical Cable Management
 - J** - Adjustable Rail ServerRack
 - K** - MCS Master Cabling Section
 - L** - Standard Rack
 - M** - CCS Combination Cabling Section
 - N** - Standard Swing Gate Wall Rack
 - O** - Cube-iT PLUS® Cabinet System
 - P** - ThinLine II Wall-Mount Cabinet
 - Q** - Telecommunications Grounding Bar
 - R** - Cable Runway



800-834-4969 • www.chatsworth.com • techsupport@chatsworth.com

Reproduction in any format, printed or electronic, without written consent is strictly prohibited.

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.

©2014 Chatsworth Products, Inc. All rights reserved. Chatsworth Products, CPI, CPI Passive Cooling, eConnect, MegaFrame, Saf-T-Grip, Seismic Frame, SlimFrame, TeraFrame, GlobalFrame, Cube-iT Plus, Evolution, OnTrac, QuadraRack and Velocity are federally registered trademarks of Chatsworth Products. Simply Efficient is a trademark of Chatsworth Products. All other trademarks belong to their respective companies. Rev.8 01/14 MKT-60020-138

RACK SYSTEMS	
L Two-Post Rack Systems	
<i>High strength, fixed two-post racks with small footprints.</i>	
48353-703	Universal Rack, 7'H (2.1 m) x 19"EIA x 15"D (381 mm), 45U, UL Listed, Supports 1500 lb (680 kg), Black
55053-703	Standard Rack, 7'H (2.1 m) x 19"EIA x 15"D (381 mm), 45U, UL Listed, Supports 1000 lb (453.6 kg), Black
66383-703	Standard Rack, 7'H (2.1 m) x 23"W x 18"D (381 mm), 45U, UL Listed, Supports 1000 lb (453.6 kg), Black
<i>Other heights, styles and finishes available.</i>	
Shelves and Trays for 2-Post Rack Systems	
10758-701	Small Peripheral Shelf, 2U x 19"EIA x 10"D (254 mm), Supports 50 lb (22.7 kg)
11054-719	26" Deep Shelf, 5U x 19"EIA x 26"D (660 mm), Supports 150 lb (68.0 kg)
11164-719	Heavy-Duty Equipment Shelf, 5U x 19"EIA x 20"D (504 mm), Supports 200 lb (90.7 kg)
11231-719	Double-Sided Vented Shelf, 4U x 19"EIA x 21.75"D (552 mm), Supports 100 lb (45.4 kg)
11245-719	Adjustable Monitor Shelf, 3U x 19"EIA x 18"D (460 mm), Supports 110 lb (49.9 kg)
11359-719	Low Profile Shelf, Vented, 2U x 19"EIA x 20"D (504 mm), Supports 60 lb (27.2 kg)
13082-719	Lockable Storage Drawer, 2U x 19"EIA x 20"D (510 mm), Supports 100 lb (45.4 kg)
40074-700	Single-Sided Shelf, 3U x 19"EIA x 15"D (380 mm), Supports 50 lb (22.7 kg)
40117-719	Single-Sided Vented Shelf, 3U x 19"EIA x 15"D (380 mm), Supports 50 lb (22.7 kg)
40108-719	Double-Sided Shelf, 4U x 19"EIA x 21.75"D (552.5 mm), Supports 100 lb (45.4 kg)
2-Post Rack System Accessories	
10629-119	Raised Floor Rack Support, 10"-16"H (250 mm to 410 mm), 19"W x 15"D (381 mm)
40604-003	Rack Installation Kit, Concrete Floor, (4) 1/2" Thread Components
12091-719	Equipment Tie-Down Bracket, 19"EIA, for Seismic Areas
12752-719	anyServer Bracket, 2U x 19"EIA, 9"-13"D (230 mm - 330 mm), Supports 120 lb (54.4 kg)
Seismic Frame® Two-Post Rack (not shown)	
<i>NEBS Zone 4 with 1000 lb (453.6 kg) load rating for seismic areas.</i>	
13853-703	7'H (2.1 m) x 19"EIA x 15"D, (380 mm) base, 44U, Supports 1000 lb (453.6 kg), Black
13883-703	7'H (2.1 m) x 23"W x 15"D (380 mm) base, 44U, Supports 1000 lb (453.6 kg), Black
13704-703	Vertical Cabling Section, Double-Sided, 6"W (150 mm)
13702-001	Seismic Frame Two-Post Rack Concrete Floor Anchor Kit
<i>Includes threaded zinc rails. Other styles and finishes available.</i>	
Adjustable QuadraRack® (ADR) (not shown)	
<i>Threaded equipment mounting rails for network switches and shelves.</i>	
15216-703	7'H (2.1 m) x 19"EIA, 22.6"D - 28.5"D (575 mm - 725 mm), 45U, Supports 2000 lb (907.2 kg), Black
15217-703	7'H (2.1 m) x 19"EIA, 29.5"D - 35.4"D (750 mm - 900 mm), 45U, Supports 2000 lb (907.2 kg), Black
15218-703	7'H (2.1 m) x 19"EIA, 36.4"D - 42.3"D (925 mm - 1075 mm), 45U, Supports 2000 lb (907.2 kg), Black
<i>Other sizes and finishes available. Square-punched equipment mounting rails also available.</i>	
Adjustable QuadraRack® (ADR) Accessories	
15255-702	Vented Shelf, 1U x 19"EIA x 20.7"D (526.5 mm), Supports 200 lb (90.7 kg), Black
15255-703	Vented Shelf, 1U x 19"EIA x 27.6"D (701.6 mm), Supports 200 lb (90.7 kg), Black
15255-704	Vented Shelf, 1U x 19"EIA x 34.5"D (876.5 mm), Supports 200 lb (90.7 kg), Black
15235-705	Equipment Support Rails, 35.4"D - 39.3"D (900 mm - 1000 mm), Supports 200 lb (90.7 kg), Black
15235-706	Equipment Support Rails, 40.3"D - 44.2"D (1025 mm - 1125 mm), Supports 200 lb (90.7 kg), Black
15205-701	Mounting Bracket, for 6"W - 24"W (150 mm - 600 mm), Cable Runway, Black
<i>Other sizes, styles and finishes available.</i>	
J Adjustable Rail ServerRack (ARSR)	
<i>Square-punched equipment mounting rails use cage nuts to mount a variety of server equipment.</i>	
15253-703	7'H (2.1 m) x 19"EIA x 23.6"D (600 mm), 45U, 2200 lb (1000 kg), Black
15254-703	7'H (2.1 m) x 19"EIA x 35.4"D (900 mm), 45U, 2200 lb (1000 kg), Black
<i>Other sizes and finishes available. Threaded equipment mounting rails also available.</i>	
Adjustable Rail ServerRack (ARSR) Accessories	
15270-702	Adjustable Rail ServerRack Side Panel, 7'H x 23.6"D (2.1 m x 600 mm), Black
15285-701	Equipment Support Rails, for 23.6"D (600 mm) Racks
G Velocity® Standard Pack	
<i>Easy to use solution for managing equipment and cabling at the cross-connect.</i>	
57011-703	(1) Standard Rack, 45U x 19"EIA; (1) Velocity Single-Sided Vertical Cable Manager 3.6"W (91 mm); and (1) Rack Installation Kit for Concrete Floors, Black
57012-703	(1) Standard Rack, 45U x 19"EIA; (1) Velocity Double-Sided Vertical Cable Manager 3.6"W (91 mm); and (1) Rack Installation Kit for Concrete Floors, Black
57013-703	(1) Standard Rack, 45U x 19"EIA; (1) Velocity Single-Sided Vertical Cable Manager 6.0"W (150 mm); and (1) Rack Installation Kit for Concrete Floors, Black
57014-703	(1) Standard Rack, 45U x 19"EIA; (1) Velocity Double-Sided Vertical Cable Manager 6.0"W (150 mm); and (1) Rack Installation Kit for Concrete Floors, Black

CABINET & ENCLOSURE SYSTEMS	
A F-Series TeraFrame® Gen 3 Cabinet System	
<i>Stores servers in enterprise data centers, computer rooms and network facilities.</i>	
FF1N-113B-C42-B	84.6"H x 23.6"W x 43.3"D (2149 mm x 600 mm x 1100 mm), 45U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
FF1U-113B-C42-B	84.6"H x 23.6"W x 47.2"D (2149 mm x 600 mm x 1200 mm), 45U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
FF2N-113B-C42-B	84.6"H x 27.6"W x 43.3"D (2149 mm x 700 mm x 1100 mm), 45U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
FF2U-113B-C42-B	84.6"H x 27.6"W x 47.2"D (2149 mm x 700 mm x 1200 mm), 45U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
FF3U-113B-C42-B	84.6"H x 31.5"W x 47.2"D (2149 mm x 800 mm x 1200 mm), 45U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
<i>Cabinet includes top panel, two side panels and perforated front and rear doors. Order thermal, power and cable management accessories separately. Other options and finishes available.</i>	
S F-Series TeraFrame® Gen 3 Cabinet System with Vertical Exhaust Duct	
<i>Isolate and remove hot exhaust air from the cabinet to an overhead return.</i>	
FF1U-111B-C52-B	84.6"H x 23.6"W x 47.2"D (2149 mm x 600 mm x 1200 mm), 45U, with 20" - 34"H (508 mm - 863 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg), Black
FF1U-111B-C62-B	84.6"H x 23.6"W x 47.2"D (2149 mm x 600 mm x 1200 mm), 45U, with 34" - 60"H (863 mm - 1523 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg), Black
FF2U-111B-C52-B	84.6"H x 27.6"W x 47.2"D (2149 mm x 700 mm x 1200 mm), 45U, with 20"-34"H (508 mm - 863 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg)
FF2U-111B-C62-B	84.6"H x 27.6"W x 47.2"D (2149 mm x 700 mm x 1200 mm), 45U, with 34"-60"H (863 mm - 1523 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg)
<i>Cabinet includes top panel with duct, two side panels, perforated front door and a solid rear door. Order thermal, power and cable management accessories separately. Other finishes and options available.</i>	
D N-Series TeraFrame® Gen 3 Network Cabinet	
NF1U-113C-C42-1	83.5"H x 31.5"W x 47.2"D (2122 mm x 800 mm x 1200 mm), 45U, 19"EIA, Side Airflow, Supports 2500 lb (1134 kg), Black
NF5U-113C-C42-1	83.5"H x 40.0"W x 47.2"D (2122 mm x 1016 mm x 1200 mm), 45U, 19"EIA, Side Airflow, Supports 2500 lb (1134 kg), Black
NF7U-113C-C42-1	83.5"H x 31.5"W x 47.2"D (2122 mm x 800 mm x 1200 mm), 45U, 19"EIA, Front Airflow, Supports 2500 lb (1134 kg), Black
NF8U-113C-C42-1	83.5"H x 40.0"W x 47.2"D (2122 mm x 1016 mm x 1200 mm), 45U, 19"EIA, Front Airflow, Supports 2500 lb (1134 kg), Black
<i>Cabinet includes top panel with duct, two side panels, perforated front and rear doors and internal side or front airflow air dams for a network switch. Other finishes and options available.</i>	
U N-Series TeraFrame® Gen 3 Network Cabinet with Vertical Exhaust Duct	
NF7U-115C-C52-1	83.5"H x 31.5"W x 47.2"D (2122 mm x 800 mm x 1200 mm), 45U, 19"EIA, Front Airflow, 20"-34" (508 mm-863 mm) Vertical Exhaust Duct, Supports 2500 lb (1134 kg), Black
NF5U-114C-C62-1	83.5"H x 40.0"W x 47.2"D (2122 mm x 1016 mm x 1200 mm), 45U, 19"EIA, Side Airflow, 34"-60" (863 mm-1523 mm) Vertical Exhaust Duct, Supports 2500 lb (1134 kg), Black
<i>Cabinet includes top panel with duct, two side panels, perforated front and rear doors and internal side or front airflow air dams for a network switch. Other finishes and options available.</i>	
B GF-Series GlobalFrame® Gen 2 Cabinet System	
<i>Industry Standard, cost effective, general purpose cabinet for computer and equipment rooms.</i>	
GF-1A220-CB	79.4"H x 23.6"W x 39.4"D (2016 mm x 600 mm x 1000 mm), 42U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
GF-1A420-CB	79.4"H x 23.6"W x 47.2"D (2016 mm x 600 mm x 1200 mm), 42U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
GF-1C120-CB	79.4"H x 31.5"W x 31.5"D (2016 mm x 800 mm x 800 mm), 42U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
GF-1C220-CB	79.4"H x 31.5"W x 39.4"D (2016 mm x 800 mm x 1000 mm), 42U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
GF-1C420-CB	79.4"H x 31.5"W x 47.2"D (2016 mm x 800 mm x 1200 mm), 42U, 19"EIA, 6-Slide Supports 3000 lb (1360 kg), Black
<i>Cabinet includes top panel, two side panels, perforated front and rear doors and casters. Order thermal, power and cable management accessories separately. Other options and finishes available.</i>	
T GF-Series GlobalFrame® Gen 2 Cabinet System with Vertical Exhaust Duct	
<i>Isolate and remove hot exhaust air from the cabinet to an overhead return. Other sizes and finishes available.</i>	
GF-1A421-CB	79.4"H x 23.6"W x 47.2"D (2016 mm x 600 mm x 1200 mm), 42U, 19"EIA, 20"-34"H (508 mm - 863 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg), Black
GF-1A422-CB	79.4"H x 23.6"W x 47.2"D (2016 mm x 600 mm x 1200 mm), 42U, 19"EIA, 34"-60"H (863 mm - 1523 mm) Vertical Exhaust Duct, Supports 3000 lb (1360 kg), Black
<i>Cabinet includes top panel with duct, two side panels, perforated front door, solid rear door, bottom panel and casters. Order thermal, power and cable management accessories separately.</i>	

CABINET & ENCLOSURE SYSTEMS	
C M-Series MegaFrame® Cabinet System	
<i>General purpose, light weight aluminum cabinet delivers partially assembled for easier handling.</i>	
M1033-741	84"H x 27.3"W x 32.1"D (2130 mm x 694 mm x 816 mm), 45U, 19"EIA Supports 2000 lb (907.2 kg), Black
M1053-741	84"H x 27.3"W x 38.1"D (2130 mm x 694 mm x 968 mm), 45U, 19"EIA Supports 2000 lb (907.2 kg), Black
M1043-741	84"H x 27.3"W x 41.1"D (2130 mm x 694 mm x 1045 mm), 45U, 19"EIA Supports 2000 lb (907.2 kg), Black
<i>Cabinet includes top panel, two side panels and perforated front and rear doors. Order thermal, power and cable management accessories separately. Other options and finishes available.</i>	
Seismic Frame® Cabinet System (not shown)	
<i>Steel inner-frame; Rated Zone 4 compliant to BellCore GR-63-CORE for NEBS, Section 4.4.1.1</i>	
11972-742	84"H x 27.3"W x 38.1"D (2130 mm x 694 mm x 968 mm), 43U, 19"EIA Supports 800 lb (362.9 kg), Black
<i>Cabinet includes top panel, two side panels and perforated front and rear doors. Order thermal, power and cable management accessories separately. Other options and finishes available.</i>	
Thermal Management Accessories or Cabinet & Enclosure Systems	
<i>CPI thermal management accessories prevent re-circulation of air within the cabinet.</i>	
39085-C03	Air Dam Kit for 45U x 23.6"W (600 mm) F-Series TeraFrame Gen 3 Cabinet
39085-C00	Air Dam Kit for 42U x 23.6"W (600 mm) GF-Series GlobalFrame Gen 2 Cabinet
39132-C00	Bottom Panel for 23.6"W (600 mm) F-Series Gen 3 TeraFrame or GF-Series Gen 2 GlobalFrame Cabinets
13336-710	Air Dam Kit for M-Series MegaFrame Cabinet
39133-001	Equipment Rail Grommet Kit for 27.6"W (700 mm) or 31.5"W (800 mm) GF-Series GlobalFrame Gen 2 Cabinet
34537-000	Snap-In Filler Panel, 1U x 19"EIA, Black
34538-000	Snap-In Filler Panel, 2U x 19"EIA, Black
<i>Add Air Dam Kit/Rail Seal Kit, Bottom Panel, Equipment Rail Grommet Kit and Snap-In Filler Panels to cabinets to block airflow around rack-mount equipment. Other sizes and finishes available.</i>	
Shelves for Cabinet & Enclosure Systems	
13517-701	Rack-Mount Cable Shelf, 1U x 19"EIA
11913-719	Sliding Vented Shelf, 2U x 19"EIA, 32"D (810mm), Supports 160 lb (72.6 kg)
13083-719	Lockable Storage Drawer, 3U x 19"EIA x 20"D (510 mm), Supports 100 lb (45.4 kg)
12700-719	Extra Heavy-Duty Sliding Shelf, 2U x 19"EIA, 26"D (660 mm), Supports 300 lb (136.1 kg)
12610-719	Low Profile Fixed Vented Shelf, 1U x 19"EIA, 20" - 36" D (510 mm - 910 mm), Supports 100 lb (45.4 kg)
Casters for Cabinet & Enclosure Systems	
13203-001	Caster Kit for MegaFrame Cabinet
<i>Other accessory options available.</i>	
Installation Hardware for Cabinet & Enclosure Systems	
12637-001	Equipment Mounting Hardware, M6, Pack of 25
12639-001	Equipment Mounting Hardware, #12-24, Pack of 25
40604-003	Universal Rack/Cabinet Installation Kit, Concrete Floor, 1/2" Hardware
Keyboard, Video and Mouse (KVM Switches)	
<i>Share a common set of peripherals with all rack-mount equipment and/or access equipment remotely over an IP connection through a KVM switch. Contact CPI Technical Support for configuration assistance.</i>	
Electronic Locking System (ELS)	
<i>Upgrade to electronic locks on F-Series TeraFrame Gen 3 and GF-Series GlobalFrame Gen 2 Cabinet for automated and remote access control. Contact CPI Technical Support for ordering assistance.</i>	
Power Distribution Units (PDUs)	
<i>Single-phase and three-phase, Basic, Monitored and Switched outlet vertical PDUs are available for all cabinet systems. Contact CPI Technical Support for configuration assistance.</i>	
Environmental Monitoring Solutions	
<i>Provide critical automated environmental monitoring, logging & reporting within cabinets and equipment rooms. Contact CPI Technical Support for configuration assistance.</i>	
E Aisle Containment Solutions	
<i>Enclose or duct the hot or cold aisle between adjacent rows of F-Series, N-Series and GF-Series Cabinets. Contact CPI Technical Support for configuration assistance.</i>	

WALL-MOUNT SYSTEMS	
O CUBE-iT PLUS® Cabinet System	
<i>Wall-mounted equipment storage with easy access to the rear of equipment. 60"H (1520 mm) and 72"H (1830 mm) are wall mounted and floor supported. Other sizes and finishes available.</i>	
11890-724	24"H (610 mm) x 19"EIA x 18"D (460 mm), 12U, Supports 200 lb (90.7 kg), Black
11840-724	24"H (610 mm) x 19"EIA x 24"D (610 mm), 12U, Supports 200 lb (90.7 kg), Black
11890-736	36"H (910 mm) x 19"EIA x 18"D (460 mm), 18U, Supports 200 lb (90.7 kg), Black
11840-736	36"H (910 mm) x 19"EIA x 24"D (610 mm), 18U, Supports 200 lb (90.7 kg), Black
11890-748	48"H (1220 mm) x 19"EIA x 18"D (460 mm), 26U, Supports 200 lb (90.7 kg), Black
11840-748	48"H (1220 mm) x 19"EIA x 24"D (610 mm), 26U, Supports 200 lb (90.7 kg), Black
13492-760	60"H (1520 mm) x 19"EIA x 24"D (610 mm), 33U, Supports 1000 lb (453.6 kg), Black
13493-760	60"H (1520 mm) x 19"EIA x 30"D (760 mm), 33U, Supports 1000 lb (453.6 kg), Black
13492-772	72"H (1830 mm) x 19"EIA x 24"D (610 mm), 40U, Supports 1000 lb (453.6 kg), Black
13493-772	72"H (1830 mm) x 19"EIA x 30"D (760 mm), 40U, Supports 1000 lb (453.6 kg), Black
CUBE-iT PLUS® Cabinet System Accessories	
12803-701	Light for CUBE-iT, 115 VAC, 8 Watts, 6'L cord with NEMA 5-15P plug
12804-701	Fan Kit, 115 VAC, 100 CFM, Black
12805-701	Filter Kit for Fan
12796-501	45" Mounting Bracket, 3U, for back of cabinet
13285-501	90° Mounting Bracket, 2U, for back of cabinet
13485-760	Vertical Cable Manager for 60"H (1520 mm) Cabinet
13485-772	Vertical Cable Manager for 72"H (1830 mm) Cabinet
<i>Other Cube-iT cabinets accessories available.</i>	
P ThinLine II Wall-Mount Cabinet System	
<i>Space saving wall-mounted cabinet. Color is black. Other finishes available.</i>	
13050-711	26"H x 26"W x 5"D (660 mm x 660 mm x 130 mm), 2U, Supports 100 lb (45.4 kg)
13050-712	26"H x 26"W x 8.5"D (660 mm x 660 mm x 216 mm), 4U, Supports 100 lb (45.4 kg)
13050-713	26"H x 26"W x 12"D (660 mm x 660 mm x 300 mm), 6U, Supports 100 lb (45.4 kg)
13050-721	36"H x 26"W x 5"D (910 mm x 660 mm x 130 mm), 2U, Supports 100 lb (45.4 kg)
13050-722	36"H x 26"W x 8.5"D (910 mm x 660 mm x 216 mm), 4U, Supports 100 lb (45.4 kg)
13050-723	36"H x 26"W x 12"D (910 mm x 660 mm x 300 mm), 6U, Supports 100 lb (45.4 kg)
ThinLine II Wall-Mount Cabinet System Accessories	
13051-001	Intelligent Fan Kit, 4U & 6U Cabinet
13051-002	Intelligent Fan Kit, 2U Cabinet
Fixed Wall-Mount Equipment Rack (not shown)	
11960-718	27.4"H (696 mm) x 19"EIA x 18"D (460 mm), 12U, Supports 200 lb (90.7 kg)
11961-718	41.4"H (1052 mm) x 19"EIA x 18"D (460 mm), 20U, Supports 200 lb (90.7 kg)
11962-718	76.4"H (1941 mm) x 19"EIA x 18"D (460 mm), 40U, Supports 200 lb (90.7 kg)
<i>Color is Black. Other finishes available. 12" Deep Rack (-X12), 25" Deep Rack (-X25).</i>	
N Standard Swing Gate Rack	
11790-718	29.1" (739 mm) x 19"EIA x 18"D (460 mm), 12U, Supports 100 lb (45.4 kg)
11791-718	43.1" (1095 mm) x 19"EIA x 18"D (460 mm), 20U, Supports 100 lb (45.4 kg)
11792-718	78.1"H (1984 mm) x 19"EIA x 18"D (460 mm), 40U, Supports 100 lb (45.4 kg)
<i>Color is Black. Other finishes available. 12" Deep Rack (-X12), 25" Deep Rack (-X25). 23"W also available.</i>	
Heavy-Duty Wall-Mount Equipment Rack (not shown)	
15320-718	41.2" (1046 mm) x 19"EIA x 18"D (460 mm), 20U, Supports 350 lb (158.8 kg)
15321-718	76.2" (1935 mm) x 19"EIA x 18"D (460 mm), 40U, Supports 350 lb (158.8 kg)
<i>Color is Black. Other finishes available. 24" Deep Rack (-X24).</i>	
EasySwing Wall-Mount Rack (not shown)	
<i>Easy to ship, inventory and install — ships flat, folds open to mount on the wall.</i>	
13602-708	24.5"H (622 mm) x 19"EIA x 8"D (200 mm), 11U, Supports 85 lb (38.6 kg), Black
13604-708	38.5"H (978 mm) x 19"EIA x 8"D (200 mm), 19U, Supports 85 lb (38.6 kg), Black
13608-712	51.5"H (1308 mm) x 19"EIA x 12"D (300 mm), 26U, Supports 85 lb (38.6 kg), Black
<i>Other finishes available. 12" Deep Rack (-X12), 18" Deep Rack (-X18) and 25" Deep Rack (-X25).</i>	
Universal Swing Gate Rack (not shown)	
<i>Full-feature swing gate rack with built-in cable management capabilities. Other finishes available.</i>	
11347-719	40.4"H (1026 mm) x 19"EIA x 12"D (300 mm), 20U, Supports 150 lb (68.0 kg), Black
11348-719	40.4"H (1026 mm) x 19"EIA x 18"D (460 mm), 20U, Supports 150 lb (68.0 kg), Black
Wall-Mount Rack System Accessories	
11799-001	Vertical Cable Management Rings, Set of 6, Black Only
11583-719	Flush Mounted Wall Bracket, 2U x 19EIA, Supports 75 lb (34.0 kg)
11754-719	Extra-Capacity, Flush Mounted Wall Bracket, 6U x 19"W, Supports 150 lb (68.0 kg)
12795-701	Heavy-Duty Swing Gate Kit for 18" & 25"D (480 mm & 625 mm) Standard Swing Gate
02006-201	Saf-T-Grip® Strap, Open Loop Series, Pack of 25
02007-004	Installation Hardware for EasySwing Rack, 1/4-10 x 2" Hex Lag Screw

DISTRIBUTION RINGS	
Cable Management Rings - Wall-Mount (not shown)	
<i>Organize and secure cable bundles on wall boards.</i>	
12127-001	2"W (50 mm) Closed Composite Ring, Gray Only
10812-001	3"W (80 mm) Closed Composite Ring, Gray Only
10941-000	2"W (50 mm) Closed Metal D-Ring, Zinc Plated Only
10942-000	3"W (80 mm) Closed Metal D-Ring, Zinc Plated Only
10921-500	4"W (100 mm) Open Metal Wall Cable Support Bracket, Zinc Plated Only