

Service Parts for CUBE-iT™ Wall-Mount Cabinet

SERVICE PARTS:

This document lists service parts for the CUBE-iT™ Wall-Mount Cabinet only. Service parts include mounting rails, doors, fan kits and replacement fan filters.


To identify the correct size component, locate the product part number on the label on the bottom front corner of the cabinet frame, or take overall measurements of the cabinet frame. Please contact CPI Technical Support at 800-834-4969 or techsupport@chatsworth.com for assistance.

Front Door Assembly for CUBE-iT Wall-Mount Cabinet

- Replacement Doors

Part Number	Dimensions	Door Style	Shipping Weight lb (kg)
40950-X24	24"H x 24"W (610 mm x 610 mm)	Tempered Glass	12 (5.5)
40950-X36	36"H x 24"W (910 mm x 610 mm)	Tempered Glass	17 (7.7)
40950-X48	48"H x 24"W (1220 mm x 610 mm)	Tempered Glass	22 (10)
40960-X24	24"H x 24"W (610 mm x 610 mm)	Solid	12 (5.5)
40960-X36	36"H x 24"W (910 mm x 610 mm)	Solid	17 (7.7)
40960-X48	48"H x 24"W (1220 mm x 610 mm)	Solid	22 (10)


Note: X=Color; 7=Black and E=Glacier White

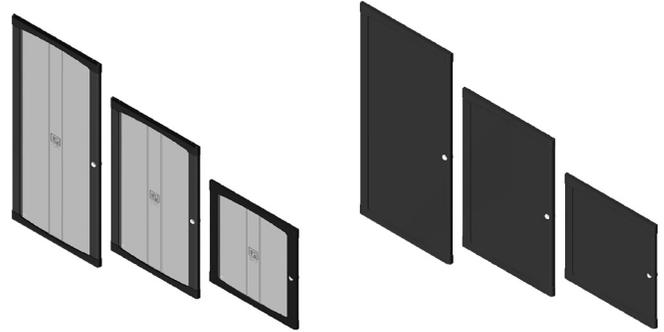

Equipment Mounting Rail Kit for CUBE-iT Wall-Mount Cabinet

- Use with equipment that needs front and rear support
- Sold in pairs
- Aluminum material

Part Number	Description	Shipping Weight lb (kg)
12787-524	12U; For 24"H (610 mm) cabinet	4 (1.8)
12787-536	19U; For 36"H (910 mm) cabinet	6 (2.7)
12787-548	26U; For 48"H (1220 mm) cabinet	8 (3.6)

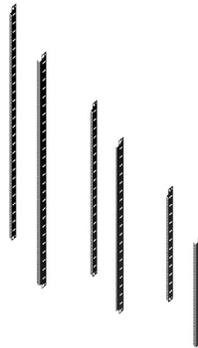

Standard Fan and Filter Kit for CUBE-iT Wall-Mount Cabinet

- Pressurizes interior of the cabinet, forcing warm air out of open vents
- Assembly Includes 1 fan, 1 filter, and 1 vent cover
- Noise Level: 39 dB (measured at 3' (1 m) distance)
- Airflow: 115 CFM (170 CMH)
- 50/60 Hz;
- 6'L (1.8 m) NEMA 5-15P/6-15P Power Cord



Part Number	Description	Shipping Weight lb (kg)
40972-001	115 Volt, 5-15P power cord	2 (0.8)
40972-002	230 Volt, 6-15P Power cord	2 (0.8)

Low-Decibel Dual-Fan and Filter Kit for CUBE-iT Wall-Mount Cabinet

- Pressurizes interior of the cabinet, forcing warm air out of open vents
- Assembly includes 2 fans and 2 filters
- Noise Level: 31 dB (measured at 3' (1 m) distance)
- Recommended placement on bottom right and left sides of the cabinet
- Airflow: 120 CFM (204 CMH)
- 50/16 Hz
- 6'L (1.8 m) NEMA 5-15P/6-15P Power Cord



Replacement Filter Kit for CUBE-iT Wall-Mount Cabinet

- Compatible with Low-Decibel Dual-Fan and Standard Fan kits

Part Number	Description	Shipping Weight lb (kg)
40973-001	Pack of 5	2 (0.9)



Part Number	Description	Shipping Weight lb (kg)
40975-001	115 Volt, 5-15P power cord	4 (1.8)
40975-002	230 Volt, 6-15P Power cord	4 (1.8)

Availability: Global



CHATSWORTH
PRODUCTS
techsupport@chatsworth.com

While every effort has been made to ensure the accuracy of all information, CPI does not accept liability for any errors or omissions and reserves the right to change information and descriptions of listed services and products.

©2018 Chatsworth Products, Inc. All rights reserved. Chatsworth Products, CliK-Nut, CPI, CPI Passive Cooling, eConnect, Evolution, GlobalFrame, MegaFrame, OnTrac, QuadraRack, RMR, Saf-T-Grip, SeismicFrame, SlimFrame, TeraFrame and Velocity are federally registered trademarks of Chatsworth Products. CUBE-iT, EuroFrame, Motive, Secure Array and Simply Efficient are trademarks of Chatsworth Products. All other trademarks belong to their respective companies. 02/18 CUBE-iT_WALL-MT_SERVICE_PART_CUT